



MC80ZBFVM

- Space required for installation (when placed on the floor)

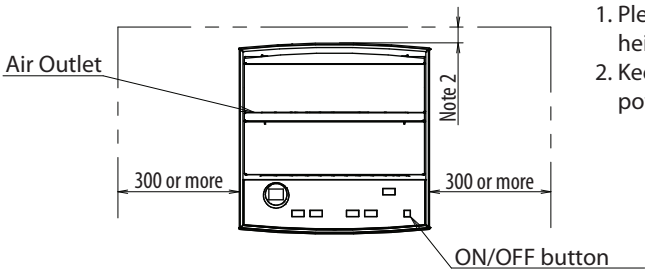

NOTES

1. Please secure 1000 or more from the height of the main body.
2. Keep a distance from the wall so that the power cable does not bend forcibly.

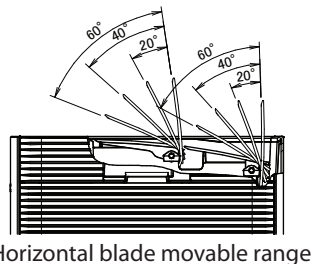

Power supply cord	
Plug type	: BF-type
Type of cordage	: H05VVH2-F
Cross Section Area	: 0.75mm ²
No. of conductors	: 2
Length outside machine	: 2000 ±50

