

 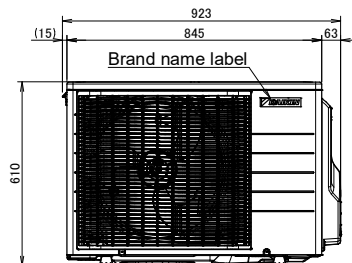
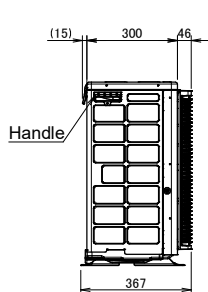
 


ARXM-A8


RXM-M-A8

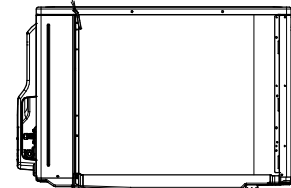

Outdoor air temperature thermistor



4 holes for anchor bolts
·M8- or ·M10·

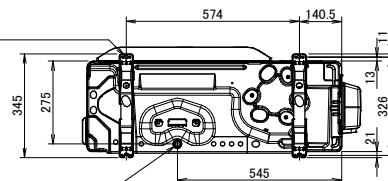


Pitch of foundation bolt holes


Drain outlet
Connection hose (inside diameter: ·15.9·mm)

Minimum space for air passage

Wall height on air outlet side < 1200 mm

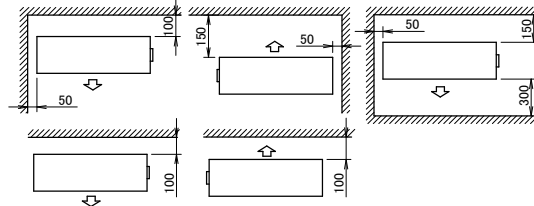

In case of removing the stop valve cover.

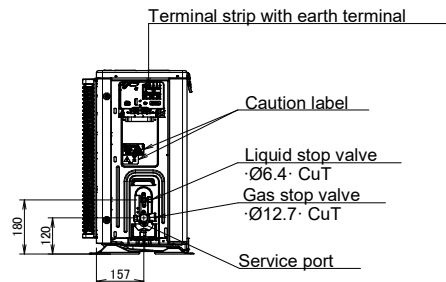

3D154038