




FTXA-AW
FTXA-BB
FTXA-BS
FTXA-BT

• Outside size

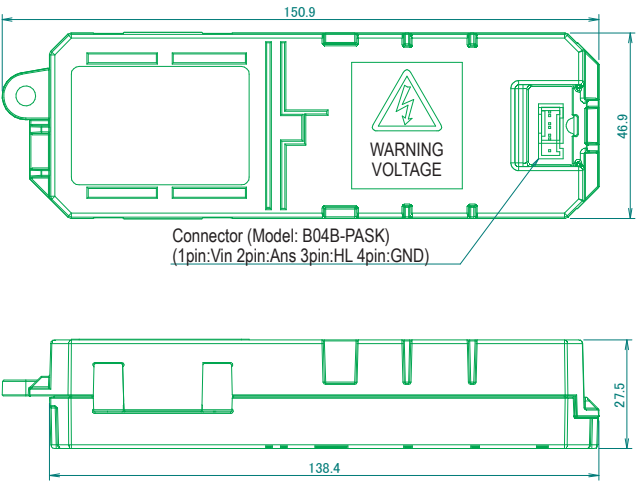


• Method of mounting

Don't blockage the vent of streamer unit.
Ensure the exit wind speed 0.2m/sec of the vent.
Ensure the spatial distance 8.5mm over at the vent of streamer unit.

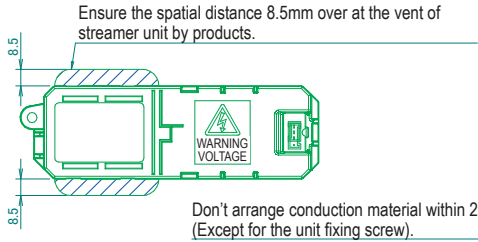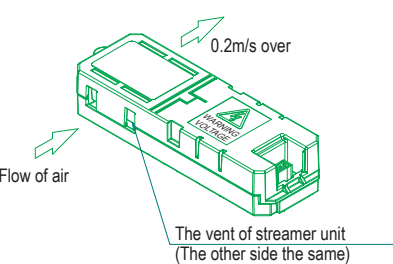

Don't arrange conduction material within 20mm of the aluminum tape (Except for the unit fixing screw).

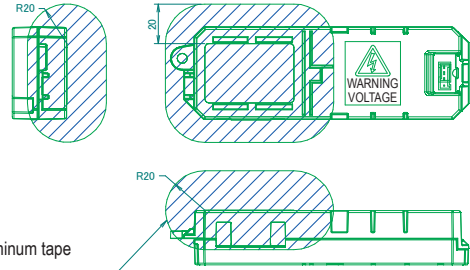

• Main specifications

Items		Contents
Outside	Outside size	150.9×46.9×27.5mm
	Weight	100g
Material of resin	Material	ABS
	Flame retardance	UL94-5VA
	Tracking index	Over CTI600V
Applicable laws		Electrical Appliance and Material Safety Act IEC60335-1(4th), IEC60335-2-65(4th)
Ambient conditions	Storage temperature	-25~70 (Non-Energization)
	Operating ambient temperature	-10~60 (Energization)
	Operating ambient humidity	5~95%RH (No dew deposit)
Basic specifications	Input voltage	14V±5%
	Maximum output voltage	6.5±0.5kV
	Rating output voltage	5.0±0.5kV
	Rating output current	Hi 55.5μA±10%
		Lo 10μA±10%
	ON/OFF	Inputted voltage into Vin (ON/OFF)
	Hi ⇄ Lo Switching	Inputted 5V into HL (Loe tap)
	Current monitor	Yes
	Detectable over current	Yes
	Detectable low voltage	Under 3kV
Generation amount of Ozone		4.26ml/hr (Hi 14±2; 50±10%RH)
Method of mounting		Fixing by the right and left hook
		Fixing by the screw section