



FTXJ-AB
FTXJ-AS
FTXJ-AW

• Outside size


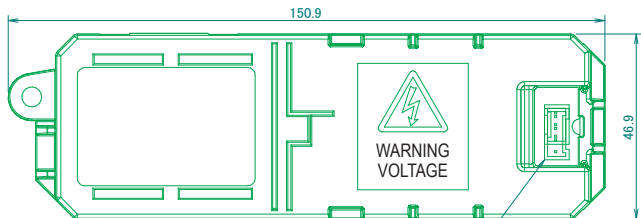


Connector (Model: B04B-PASK)
 (1pin:Vin 2pin:Ans 3pin:HL 4pin:GND)

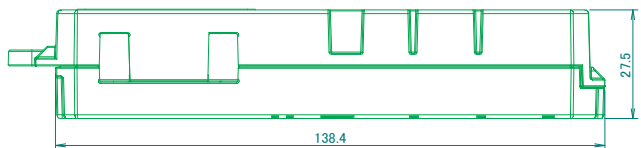


• Method of mounting

Don't blockage the vent of streamer unit.
 Ensure the exit wind speed 0.2m/sec of the vent.
 Ensure the spatial distance 8.5mm over at the vent of streamer unit.

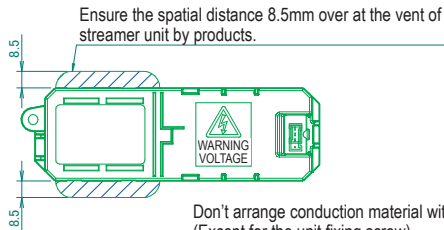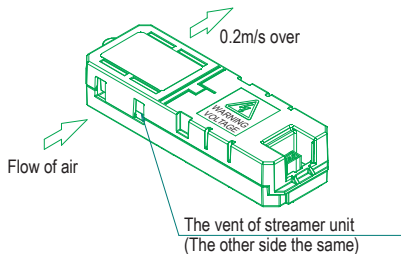

Don't arrange conduction material within 20mm of the aluminum tape
 (Except for the unit fixing screw).

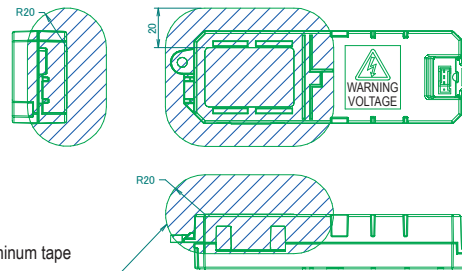

• Main specifications

Items		Contents	
Outside	Outside size	150.9×46.9×27.5mm	
	Weight	100g	
Material of resin	Material	ABS	
	Flame retardance	UL94-5VA	
	Tracking index	Over CTI600V	
Applicable laws		Electrical Appliance and Material Safety Act IEC60335-1(4th), IEC60335-2-65(4th)	
Ambient conditions	Storage temperature	-25~70 (Non-Energization)	
	Operating ambient temperature	-10~60 (Energization)	
	Operating ambient humidity	5~95%RH (No dew deposit)	
Basic specifications	Input voltage	14V±5%	
	Maximum output voltage	6.5±0.5kV	
	Rating output voltage	5.0±0.5kV	
	Rating output current	Hi	55.5μA±10%
		Lo	10μA±10%
	ON/OFF	Inputted voltage into Vin (ON/OFF)	
	Hi ↔ Lo Switching	Inputted 5V into HL (Loe tap)	
	Current monitor	Yes	
	Detectable over current	Yes	
Detectable low voltage	Under 3kV		
Generation amount of Ozone	4.26ml/hr (Hi 14±2; 50±10%RH)		
Method of mounting	Fixing by the right and left hook		
	Fixing by the screw section		